


Vacuum filter VAF-PK-6

Part number: 160239

FESTO

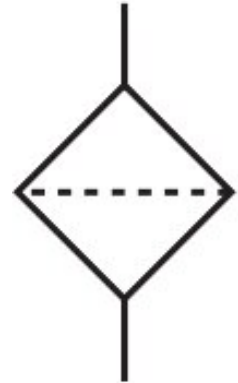

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size	4.6 mm
Mounting position	Any
Grade of filtration	50 µm
Symbol	00991483
Operating pressure	-0.95 bar ... 0 bar
Note on operating pressure	Only for use in open vacuum systems
Flow rate with vacuum = -0.075 MPa (-0.75 bar, -10.875 psi)	210 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Suitability for the production of Li-ion batteries	Suitable for battery production with reduced Cu/Zn/Ni values (F1a)
Ambient temperature	0 °C ... 40 °C
Product weight	10 g
Type of mounting	Inline installation
Pneumatic connection	PK-6 with union nut
Material union nut	POM
Note on materials	RoHS compliant
Material filter	Fabric Process automation
Material housing	Process automation
Suitable for ejector pulse	≤8 bar