


# Swivel flange SNC-50

Part number: 174385

FESTO

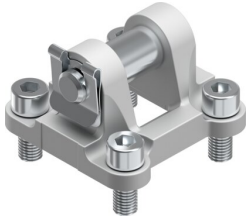

 [General operating condition](#)

## Data sheet

Feature	Value
Size	50
Based on standard	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	2.5 kN
Product weight	234 g
Note on materials	RoHS compliant
Material mounting	Die-cast aluminium
Material bolt	Steel Galvanised
Material screws	Steel Galvanised
Material lock	Spring steel Galvanised