


Swivel flange SNC-63

Part number: 174386

FESTO

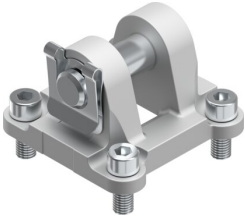

 [General operating condition](#)

Data sheet

Feature	Value
Size	63
Based on standard	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	4 kN
Product weight	332 g
Note on materials	RoHS compliant
Material mounting	Die-cast aluminium
Material bolt	Steel Galvanised
Material screws	Steel Galvanised
Material lock	Spring steel Galvanised