


Trunnion mounting kit DAMT-V1-40-A

Part number: 2214899

FESTO

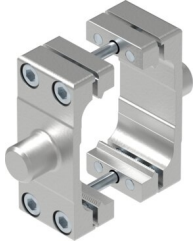

 [General operating condition](#)

Data sheet

| Feature | Value |
|--|---|
| Size | 40 |
| Based on standard | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Metals with more than 1% by mass of copper are excluded from use. Exceptions are printed circuit boards, cables, electrical connectors and coils. |
| Ambient temperature | -40 °C ... 150 °C |
| Max. load capacity | 1.5 kN |
| Product weight | 387.5 g |
| Note on materials | RoHS compliant |
| Material screws | Steel Galvanised |
| Material trunnion flange | Galvanised steel |
| Material clamping piece | Galvanised steel |
| Material rod | High-alloy stainless steel |