


Vacuum generator VAD-ME-3/8

Part number: 35556

FESTO

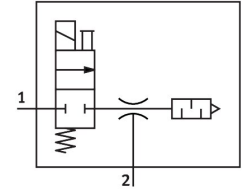

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size, Laval nozzle	2 mm
Mounting position	Any
Ejector characteristic	High vacuum
Integrated function	On/off valve, electric
Design	T-shape
Symbol	00991492
Operating pressure	1.5 bar ... 8 bar
Max. vacuum	85 %
Duty cycle	100%
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation not possible
LABS (PWIS) conformity	VDMA24364-B2-L
Media temperature	0 °C ... 40 °C
Degree of protection	IP65
Ambient temperature	0 °C ... 40 °C
Product weight	242 g
Electrical connection	Plug
Type of mounting	With female thread
Pneumatic connection, port 1	G1/4
Vacuum connection	G3/8
Material housing	Aluminium