


Intermediate-position module DADM-DGC-32-A

Part number: 541701

FESTO

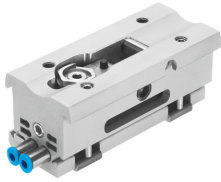

 General operating condition

Data sheet

Feature	Value
Size	32
Mounting position	Any
Position detection	Via proximity switch
Operating pressure	0.25 MPa ... 0.8 MPa
Operating pressure	2.5 bar ... 8 bar
Operating pressure	36.25 psi ... 116 psi
Max. impact speed	3 m/s
Max. swivel time	100 ms
Repetition accuracy	0.02 mm
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	530 g
Type of mounting	Clamped on cylinder DGC
Pneumatic connection	QS-4
Note on materials	RoHS compliant
Material stop screw	Steel Galvanised
Material seals	NBR
Material housing	anodised
Material lever	High-alloy stainless steel
Material clip	High-alloy stainless steel
Material nut	Steel Galvanised
Fine adjustment	2 mm
Mode of operation	Double-acting