


# Vertical pressure supply plate VABF-S3-1-P1A3-G14

FESTO

Part number: 544434

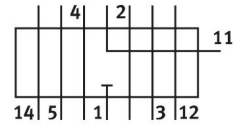

 General operating condition

## Data sheet

Feature	Value
Construction width	26 mm
Based on standard	ISO 15407-1
Mounting position	Any
Vertical pneumatic linkage	Alternative compressed air supply for 1
Symbol	00991883
Operating pressure	-0.9 bar ... 10 bar
Standard nominal flow rate (standardised to DIN 1343)	1000 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Degree of protection	IP65 NEMA 4
Ambient temperature	-5 °C ... 50 °C
Product weight	201 g
Mounting with vertical stacking	On manifold sub-base On individual sub-base
Note on materials	RoHS compliant
Material housing	Die-cast aluminium