


# Electrical sub-base VAVE-L1-1VS2-LP

Part number: 566718

FESTO

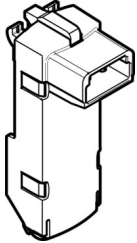

## Data sheet

 [General operating condition](#)

| Feature                         | Value                   |
|---------------------------------|-------------------------|
| Reverse polarity protection     | Bipolar                 |
| Additional functions            | Spark arresting         |
| Signal status display           | LED                     |
| Nominal operating voltage DC    | 12 V                    |
| Immunity to surge               | 0.8 kV                  |
| Pollution degree                | 3                       |
| Extended ambient temperature    | -5 - 60 °C              |
| Corrosion resistance class CRC  | 0 - No corrosion stress |
| LABS (PWIS) conformity          | VDMA24364-B1/B2-L       |
| Degree of protection            | IP40                    |
| Ambient temperature             | -5 °C ... 50 °C         |
| Mounting position               | Any                     |
| Product weight                  | 1.5 g                   |
| Electrical connection           | 2-pin<br>Socket         |
| Protective conductor connection | Not provided            |
| Type of mounting                | Clip                    |
| Housing colour                  | Black                   |
| Note on materials               | RoHS compliant          |
| Material housing                | Process automation      |