


Vertical pressure supply plate VABF-L1-P3A3-M7

Part number: 574592

FESTO

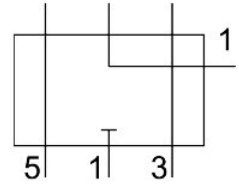

 [General operating condition](#)

Data sheet

Feature	Value
Grid dimension	10.5 mm
Max. number of valve positions	1
Symbol	00995306
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Approval	RCM c UL us - Recognised (Oil)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.45 Nm
Product weight	220 g
Pneumatic connection, port 1	M7
Note on materials	RoHS compliant
Material plate	Wrought aluminium alloy