


Vertical pressure exhaust plate VABF-L1-P7A13-M7

Part number: 574594

FESTO

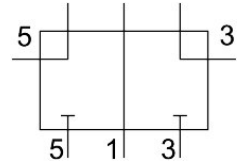

[PDF](#) General operating condition

Data sheet

| Feature | Value |
|---|-----------------------------------|
| Grid dimension | 10.5 mm |
| Max. number of valve positions | 1 |
| Symbol | 00995307 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Approval | RCM c UL us - Recognised (Oil) |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Max. tightening torque for valve mounting | 0.45 Nm |
| Product weight | 220 g |
| Pneumatic connection, port 3 | M7 |
| Pneumatic connection, port 5 | M7 |
| Note on materials | RoHS compliant |
| Material plate | Wrought aluminium alloy |