


Supply plate VABF-B10-30-P1A4-G38

Part number: 8026434

FESTO

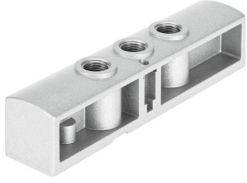

 [General operating condition](#)

Data sheet

Feature	Value
Operating pressure	-0.09 MPa ... 1 MPa
Operating pressure	-0.9 bar ... 10 bar
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	6 Nm
Product weight	167 g
Type of mounting	With through-hole
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 3	G3/8
Pneumatic connection, port 5	G3/8
Note on materials	RoHS compliant
Material supply plate	Die-cast aluminium