


X-fitting NPFC-X-R12-3G12-MFFF

Part number: 8030266

FESTO

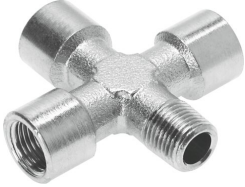

 [General operating condition](#)

Data sheet

Feature	Value
Material threaded fitting	Brass, nickel-plated
Size of pack	10
Operating pressure	-0.95 bar ... 50 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-::-]
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-20 °C ... 150 °C
Product weight	146.7 g
Pneumatic connection, port 1	R1/2
Pneumatic connection, port 2	G1/2
Note on materials	RoHS compliant