


Branching modules FRZ-...-RR and FRM-...-RR

Flowrate: 250...17400 l/min

Cleanroom class ISO 4 (FS209E class 10)


Branching module, without non-return valve, without threaded connection plate for D-Micro series
FRZ-D-MICRO-RR

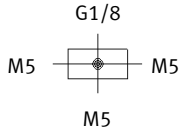


- This branching module is mounted after the regulator type LR-...-MICRO-RR-SA or after the filter regulator type LFR-...-MICRO-RR-SA

Accessories


Mounting bracket
HFOE-D-MICRO

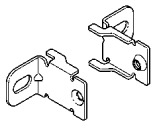

Connecting plate kit
PBL-1/8-D-MICRO

 


Branching module, without non-return valve, with threaded connection plate
FRM-...-D-...-RR

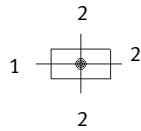

- Branching module for compressed air distribution for attachment of additional modules (pressure regulating valve, pressure switch...).
- Several additional air connections for more flexibility.
- Can be used as an intermediate outlet for different air qualities.
- Any mounting position
- Temperature range; -10...+60 °C
- Material; Die-cast zinc



Branching module, with non-return valve and threaded connection plate
FRM-H-...-D-...-RR

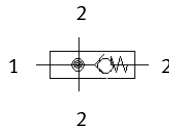

- An integrated non-return valve prevents return flow of lubricated compressed air.
- The branching module can be combined with service units of series D.
- Any mounting position
- Temperature range; -10...+60 °C
- Material; Die-cast zinc

Accessories

 Mounting bracket
HFOE-D-MINI
HFOE-D-MIDI/MAXI

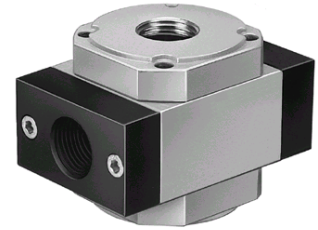


Type	Part No.	Connec-tion	Std nominal flowrate [l/min]	Input pressure [bar]	Type	Part No.	Connec-tion	Std nominal flowrate [l/min]	Input pressure [bar]	Weight [kg]
FRZ-D-MICRO-RR	15059911	M5	250	0...10	-	-	-	-	-	-
FRM-1/8-D-MINI-RR	15024773	G1/8	1500	0...16	FRM-H-1/8-D-MINI-RR	15024790	G1/8	1300	0.15...16	0.210
FRM-1/4-D-MINI-RR	15024775	G1/4	3300		FRM-H-1/4-D-MINI-RR	15024793	G1/4	2000		
FRM-3/8-D-MINI-RR	15024776	G3/8	3300		FRM-H-3/8-D-MINI-RR	15024794	G3/8	2100		
FRM-1/4-D-MIDI-RR	15024779	G1/4	3500	0.2...16	FRM-H-1/4-D-MIDI-RR	15024795	G1/4	3400	0.2...16	0.520
FRM-3/8-D-MIDI-RR	15024780	G3/8	7000		FRM-H-3/8-D-MIDI-RR	15024797	G3/8	5500		
FRM-1/2-D-MIDI-RR	15024781	G1/2	8200		FRM-H-1/2-D-MIDI-RR	15024798	G1/2	5600		
FRM-3/4-D-MIDI-RR	15024784	G3/4	8800		FRM-H-3/4-D-MIDI-RR	15024799	G3/4	5500		
FRM-1/2-D-MAXI-RR	15024786	G1/2	11700	0.25...16	FRM-H-1/2-D-MAXI-RR	15024800	G1/2	9600	0.25...16	0.900
FRM-3/4-D-MAXI-RR	15024787	G3/4	20000		FRM-H-3/4-D-MAXI-RR	15024801	G3/4	15000		
FRM-1-D-MAXI-RR	15024789	G1	17400		FRM-H-1-D-MAXI-RR	15024802	G1	13400		

Branching modules FRZ-...-RR and FRM-...-RR

Flowrate: 250...17400 l/min

Cleanroom class ISO 4 (FS209E class 10)

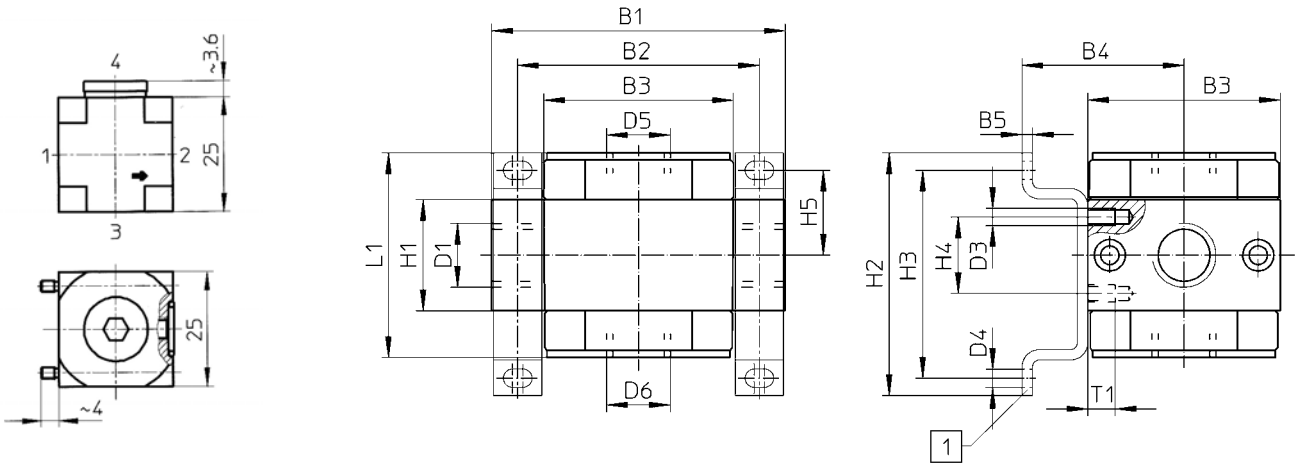

FRZ-D-MICRO-RR

FRM-...

1 Mounting bracket HFOE-D-...
(not included in scope of delivery)

Type	B1	B2	B3	B4	B5	D1	D3	D4	D5	D6	H1	H2	H3	H4	H5	L1	T1
FRM-...-H-...-D-MINI-RR	64	52	40	39	2	G1/8	M4	4,3	G1/4	G1/4	20	43	35	11	17.5	42	7
						G1/4											
						G3/8											
	70																
FRM-...-H-...-D-MIDI-RR	85	70	55	47	3	G1/4	M5	5.3	G1/2	G1/4	32	70	60	22	24.5	59	8
						G3/8											
						G1/2											
						G3/4											
FRM-...-H-...-D-MAXI-RR	96	80	66	53	3	G1/2	M5	5.3	G3/4	G1/4	32	70	60	22	24.5	70	8
						G3/4											
						G1											
	116																