


Branching module FRM-H-D-MAXI

Part number: 170689

FESTO

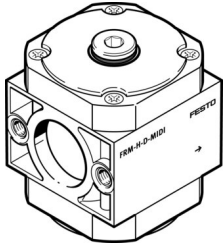

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	optional
Design	Branching module
Symbol	00991511
Operating pressure	0.025 MPa ... 1.6 MPa
Operating pressure	0.25 bar ... 16 bar
Standard nominal flow rate in main flow direction 1->2	13500 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-] Inert gases
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C ... 60 °C
Air purity class at output	Compressed air to ISO 8573-1:2010 [7:-:-] Inert gases
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Product weight	446 g
Pneumatic connection, port 3	G3/4
Pneumatic connection, port 4	G1/4
Note on materials	RoHS-compliant
Material housing	Die-cast zinc