


Axial kit EAMM-A-D50-70A

Part number: 2733783

FESTO

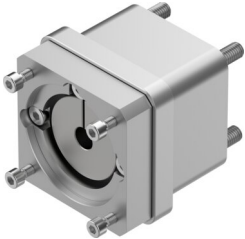

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	67.5 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	34.8 kgmm ²
Transmittable torque	17 Nm
Product weight	730 g
Interface code, actuator	D50
Interface code, motor in	70A
Note on materials	RoHS-compliant