


Intermediate-position module DADM-DGC-40-A

Part number: 541702

FESTO

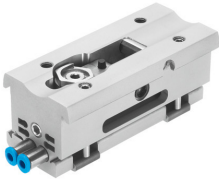

 General operating condition

Data sheet

Feature	Value
Size	40
Mounting position	optional
Position detection	Via proximity switch
Operating pressure	0.25 MPa ... 0.8 MPa
Operating pressure	2.5 bar ... 8 bar
Operating pressure	36.25 psi ... 116 psi
Max. impact speed	3 m/s
Max. swivel time	300 ms
Repetition accuracy	0.02 mm
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Product weight	970 g
Type of mounting	Clamped to cylinder DGC
Pneumatic connection	M5
Note on materials	RoHS-compliant
Material stop screw	Steel Galvanised
Material seals	TPE-U(PU)
Material housing	Anodised
Material lever	High-alloy stainless steel
Material clip	High-alloy stainless steel
Material nut	Steel Galvanised
Fine adjustment	4 mm
Mode of operation	Double-acting