


Axial kit EAMM-A-D40-55A

Part number: 543153

FESTO

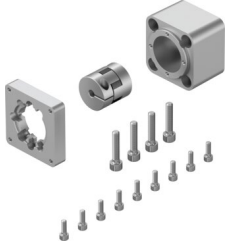

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	49.2 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	5.87 kgmm ²
Transmittable torque	12.5 Nm
Product weight	350 g
Interface code, actuator	D40 D40C
Interface code, motor in	55A
Note on materials	RoHS-compliant