


Connecting cable VMPAL-KMSK-S-SD25-IP67-2.5

Part number: 560413

FESTO

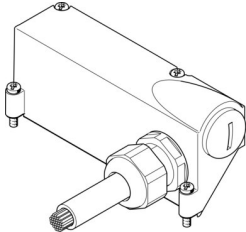

 [General operating condition](#)

Data sheet

Feature	Value
Product weight	610 g
Electrical connection	Cable with plug
Cable length	2.5 m
Cable characteristic	Suitable for energy chains
Min. cable bending radius	63 mm
Cable diameter	12.5 mm
Cable structure	25 x 0.34 mm ²
Degree of protection	IP67 To IEC 60529
Ambient temperature with moving cable	-5 °C ... 80 °C
CE mark (see declaration of conformity)	In accordance with EU RoHS Directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Note on materials	RoHS-compliant
Corrosion resistance class CRC	2 - Moderate corrosion stress
Material cable sheath	TPE-U(PU)