


End plate VABE-S6-2RZ-N34

Part number: 560840

FESTO

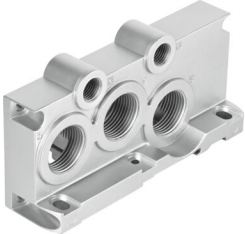

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------------|-------------------------|
| Based on standard | ISO 5599-2 |
| Mounting position | optional |
| Terminal type | 44 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Corrosion resistance class CRC | 0 - No corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Product weight | 336 g |
| Pilot air port 12 | 1/4 NPT |
| Pilot air port 14 | 1/4 NPT |
| Pneumatic connection, port 1 | 3/4 NPT |
| Pneumatic connection, port 3 | 3/4 NPT |
| Pneumatic connection, port 5 | 3/4 NPT |
| Note on materials | RoHS-compliant |
| Material end plate | Die-cast aluminium |