


Adapter VMPAL-F20-G1/4

Part number: 573914

FESTO

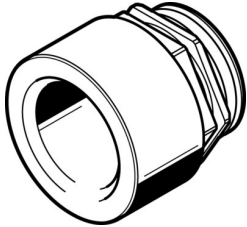

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------------|-------------------------------|
| Size of pack | 10 |
| Operating pressure | -0.09 MPa ... 1 MPa |
| Operating pressure | -0.9 bar ... 10 bar |
| Operating pressure | -13.05 psi ... 145 psi |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -5 °C ... 50 °C |
| Product weight | 55 g |
| Pneumatic connection, port 1 | Cartridge 18 mm |
| Pneumatic connection, port 2 | G1/4 |
| Note on materials | RoHS compliant |
| Material housing | Wrought aluminium alloy |