


# Vacuum filter OAFF-G3-7

Part number: 8068945

FESTO

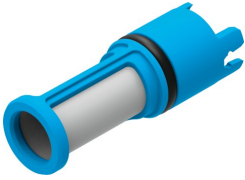

 [General operating condition](#)

## Data sheet

Feature	Value
Grade of filtration	40 µm
Size of pack	10
Symbol	00991483
Operating pressure	-0.095 MPa ... 0 MPa
Operating pressure	-0.95 bar ... 0 bar
Operating pressure	-13.775 psi ... 0 psi
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	1.5 g
Type of mounting	Push-on Snapping in
Note on materials	RoHS-compliant
Material seals	NBR
Material filter	Fabric PA
Material housing	POM
Suitable for ejector pulse	0.7 MPa
Suitable for ejector pulse	7 bar
Suitable for ejector pulse	101.5 psi