


# Control plate DADG-FM-VDE1G14

Part number: 8131548

FESTO

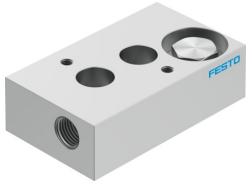

 [General operating condition](#)

## Data sheet

Feature	Value
Based on standard	VDI/VDE 3845 (NAMUR)
Mounting position	optional
Operating pressure	0.2 MPa ... 0.8 MPa
Operating pressure	2 bar ... 8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-20 °C ... 80 °C
Max. tightening torque	23 Nm
Product weight	274.5 g
Type of mounting	Direct mounting on end cap via thread
Pneumatic connection	G1/4
Note on materials	RoHS-compliant
Material seals	NBR High-alloy stainless steel
Material housing	Anodised aluminium
Material screws	Nickel-plated brass