


# Stem actuated valve V/O-3-PK-3

Part number: 10747

FESTO

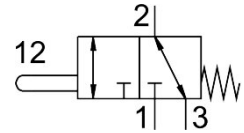

[PDF](#) General operating condition

## Data sheet

Feature	Value
Valve function	3/2-way, monostable, open/closed
Type of actuation	Mechanical
Standard nominal flow rate (standardised to DIN 1343)	80 l/min
pneumatic working port	PK-3
Operating pressure	0 bar ... 8 bar
Design	Piston seat
Nominal size	2.5 mm
Type of piloting	Direct
Symbol	00991294
Operating medium	Compressed air to ISO 8573-1:2010 [-:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Actuating force	17 N
Actuating force, normally closed	17 N
Actuating force, normally open	24 N
Product weight	20 g
Type of mounting	With through-hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Material seals	NBR
Material housing	POM