 



Solenoid valve

JMFH-5-PK-3

Part number: 4447

FESTO

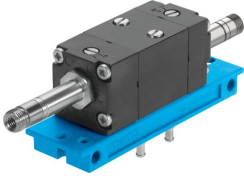

General operating condition

Data sheet

Feature	Value
Valve function	5/2 bistable
Standard nominal flow rate (standardised to DIN 1343)	105 l/min
pneumatic working port	PK-3
Operating pressure	2 bar ... 8 bar
Design	Poppet seat
Nominal size	2.5 mm
Sealing principle	Soft
Symbol	00995753
Switching time reversal	13 ms
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	0 °C ... 60 °C
Ambient temperature	0 °C ... 40 °C
Product weight	380 g
Type of mounting	On sub-base On mounting frame With through-hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Pneumatic connection, port 3	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Note on materials	RoHS-compliant
Material sub-base	Aluminium Anodised
Material seals	NBR
Material housing	Anodised