


Pushbutton valve F-3-M5

Part number: 4452

FESTO

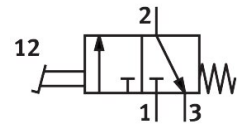

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|-----------------------------|
| Valve function | 3/2-way, closed, monostable |
| Standard nominal flow rate (standardised to DIN 1343) | 80 l/min |
| pneumatic working port | M5 |
| Operating pressure | -0.9 bar ... 8 bar |
| Type of reset | Mechanical spring |
| Type of piloting | Direct |
| Symbol | 00991101 |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L |
| Product weight | 235 g |
| Pneumatic connection, port 1 | M5 |
| Pneumatic connection, port 2 | M5 |
| Pneumatic connection, port 3 | M5 |