


Distributor block FR-12-M5

Part number: 4525

FESTO

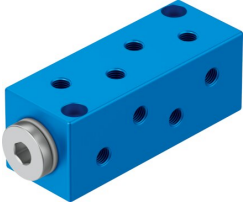

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size	4.1 mm
Mounting position	optional
Operating pressure complete temperature range	0 bar ... 16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 60 °C
Nominal torque	3.5 Nm
Tolerance for nominal tightening torque	± 20%
Product weight	40 g
Number of outputs	12
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/8
Pneumatic connection, port 2	Female thread M5
Note on materials	RoHS-compliant
Material housing	Aluminium Anodised