 



# pneumatic valve JH-5-1/8

Cikkszám: 8823

FESTO

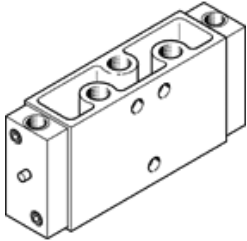

 [Általános üzemi körülmények](#)

[→ Support Portal](#)

## Termék-megbízhatósági adatlap

The information in this "Product reliability data sheet" is based on products being used as intended. This includes complying with all specifications in data sheets, catalogues, user documentation and the general operating conditions. The user alone is responsible for determining whether a product is suitable for a particular application.

Jellemző	Érték
Well-trying component <sup>1)</sup>	Yes
Service-life value B <sub>10</sub> <sup>2)</sup>	10 Mio cycles
Max. switching frequency	12 Hz
Design characteristics	Remains in switching position on signal switch-off (bistable valve) Not free of overlap
Lap	Underlap

- 1) The product is a well-trying product for a safety-related application according to ISO 13849-1. The relevant basic and well-trying safety principles according to ISO 13849-2 for this product are fulfilled. The suitability of the product for a precise application must be verified and confirmed by the user.
- 2) The ascertainment of characteristic service life values is generally based on the ISO 19973 "Pneumatic fluid power - Assessment of component reliability by testing".