


Pneumatic valve J-3-PK-3

Part number: 10772

FESTO

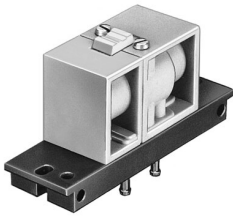

 General operating condition

Data sheet

Feature	Value
Valve function	3/2-way, double solenoid
Standard nominal flow rate (standardised to DIN 1343)	100 l/min
pneumatic working port	PK-3
Operating pressure	-0.9 bar ... 8 bar
Design	Piston gate valve
Nominal size	2.5 mm
Symbol	00991377
Switching time reversal	7 ms
Explosion protection	The information in the certificate must be observed! Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-10 °C ... 60 °C
Product weight	75 g
Type of mounting	On sub-base On mounting frame With through-hole
Auxiliary pilot air port 12	PK-3
Auxiliary pilot air port 14	PK-3
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 4	PK-3
Pneumatic connection, port 5	PK-3
Material sub-base	Brass Reinforced PPS
Material seals	NBR
Material housing	Die-cast zinc