



# Clamping module EV-50-5

Part number: 184858

FESTO

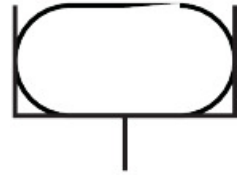

 General operating condition

## Data sheet

Feature	Value
Stroke	5 mm
Clamping surface	Ø 50
Mounting position	optional
Mode of operation	Single-acting
Symbol	00991208
Operating pressure	≤0.6 MPa
Operating pressure	≤6 bar
Operating pressure	≤87 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper are excluded from use. Exceptions are printed circuit boards, cables, electrical plug connectors and coils
Ambient temperature	-10 °C ... 40 °C
Product weight	68 g
Type of mounting	With through-hole
Pneumatic connection	M3
Material housing	Die-cast aluminium
Material membrane	TPE-U(PU)