


# Shut-off valve HE-G3/8-LO

Part number: 197133

FESTO

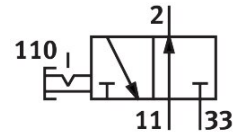

General operating condition

## Data sheet

Feature	Value
Design	Piston gate valve
Type of actuation	Manual
Sealing principle	Soft
Exhaust-air function	Cannot be throttled
Manual override	None
Symbol	00991672
Valve function	3/2-way, double solenoid
Operating pressure	1 bar ... 10 bar
C value	20.95 l/sbar
b value	0.42
Standard nominal flow rate (standardised to DIN 1343)	5200 l/min
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Type of mounting	Inline installation With through-hole
Mounting position	Any
Flow direction	Non-reversible
Product weight	1100 g
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 2	G3/8
Pneumatic connection, port 3	G1
Material seals	NBR TPE-U(PU)
Material housing	Die-cast aluminium PBT