


# Pushbutton valve F-3-M5

Part number: 4452

FESTO

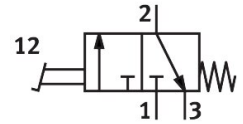

 [General operating condition](#)

## Data sheet

Feature	Value
Valve function	3/2-way, single solenoid, closed
Standard nominal flow rate (standardised to DIN 1343)	80 l/min
pneumatic working port	M5
Operating pressure	-0.9 bar ... 8 bar
Type of reset	Mechanical spring
Type of piloting	Direct
Symbol	00991101
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	235 g
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M5
Pneumatic connection, port 3	M5