


Double nipple NPFC-DS-G14-G14-M

Part number: 8142585

FESTO

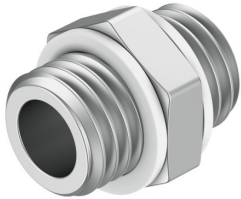

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|--|
| Material threaded fitting | Nickel-plated brass |
| Size of pack | 10 |
| Operating pressure | -0.95 bar ... 10 bar |
| Operating medium | Compressed air to ISO 8573-1:2010 [-::-] |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Ambient temperature | -10 °C ... 60 °C |
| Nominal tightening torque, pneumatic connection 1 | 9.05 Nm |
| Nominal tightening torque, pneumatic connection 2 | 9.05 Nm |
| Tolerance for nominal tightening torque | ± 20% |
| Product weight | 17.82 g |
| Pneumatic connection, port 1 | G1/4 |
| Pneumatic connection, port 2 | G1/4 |
| Note on materials | RoHS-compliant |
| Material seals | PVC |