


# Bulkhead quick connector SCK-PK-4

Part number: 9421

FESTO

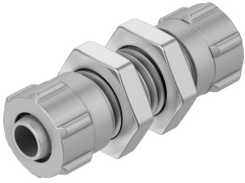

 General operating condition

## Data sheet

Feature	Value
Nominal size	3.4 mm
Mounting position	optional
Design	Bulkhead
Size of pack	10
Operating pressure complete temperature range	0 MPa ... 1.6 MPa
Operating pressure complete temperature range	0 bar ... 16 bar
Operating pressure complete temperature range	0 psi ... 232 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance class CRC	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 °C ... 150 °C
Pneumatic connection, port 1	For tubing outside diameter of 6 mm For barbed fitting I.D. 4 mm with union nut
Pneumatic connection, port 2	For tubing outside diameter of 6 mm For barbed fitting inside diameter of 4 mm with nut
Material union nut	Wrought aluminium alloy, anodised
Note on materials	RoHS-compliant
Material nut	Galvanised steel
Material connector	Wrought aluminium alloy, anodised