


Captive nut Type NRM-M6


This captive nut is snapped into the square holes of the various mounting strips. The mounting thread is M6.

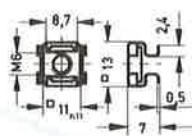


Cross bar Type NRV-1N NRV-2N NRV-4N

Cross bars and mounting rails can be mounted together in the corresponding n-grid. Intermediate grooves allow larger grids to be combined with smaller grids or to be subdivided into smaller grids. Components without n-grids can also be screwed crosswise on the cross bars.


Type NRV-1N

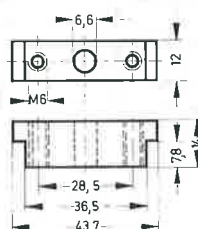

NRV-2N

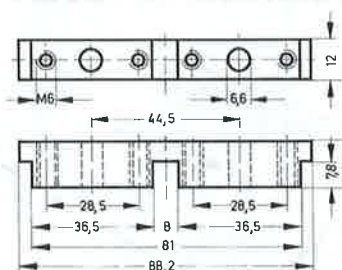

Type NRV-4N

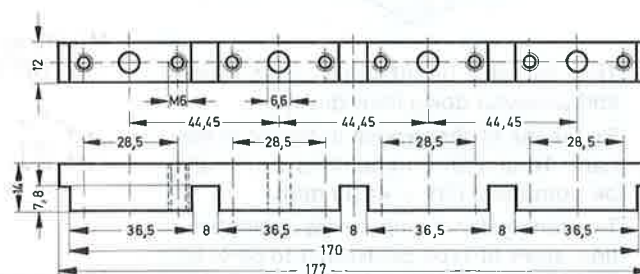


Mounting rail Type NRQ-8-480

This mounting rail is required for mounting various pneumatic components. Two rails are connected together in the corresponding n-grid. 1n and 2n sub-bases can be inserted into the groove.



Mounting bracket NRW-12/3

These brackets are used to clamp cross bars Type NRV and standard sub-bases to the mounting rails.

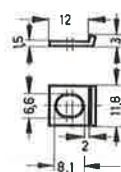

Order code		Material	Description	Delivery length	Weight kg
Part No.	Type				
7399	NRM-M6	Galvanized steel	Captive nut		0.005
9363	NRQ-8-480	Anodized aluminium	Mounting rail	0.048 m	0.060
6851	NRV-1N	Die-cast aluminium	Cross bar 1n		0.015
6852	NRV-2N		Cross bar 2n		0.032
6771	NRV-4N		Cross bar 4n		0.060
208 938		Galvanized steel	Socket head capscREW M6 x 12 DIN 84		0.004