


Distributor hollow bolt
with threaded connection, consisting of
Hollow bolt Type VT-...
and
Ring piece Type LK-...
or
Type TK-...

Distributor hollow bolts with two six out-
lets and a common air supply can be
assembled as desired from two or three
ring pieces and a suitable hollow bolt.

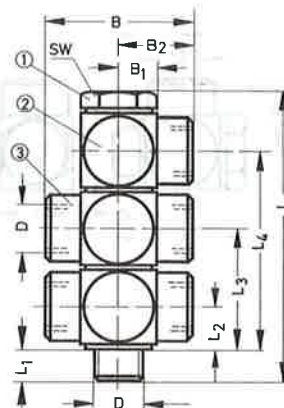

- ① Hollow bolt
- ② Ring piece Type LK
- ③ Ring piece Type TK

Hollow bolt Type	Ring pieces Type	Con- nection D	B	B ₁	B ₂	L	L ₁	L ₂	L ₃	L ₄	SW
VT- ¹ / ₈ -2	LK- ¹ / ₈	G ¹ / ₈	28	8	15.5	44	6.3	9.1	25.8	—	13
	TK- ¹ / ₈			—	—	—	—	—	—	—	—
VT- ¹ / ₈ -3	LK- ¹ / ₈	G ¹ / ₈	28	8	15.5	60.5	6.2	—	—	—	42.5
	TK- ¹ / ₈			—	—	—	—	—	—	—	—
VT- ¹ / ₄ -2- ¹ / ₄	LK- ¹ / ₄	G ¹ / ₄	39	10	21	56	8	11.6	32.8	—	17
	TK- ¹ / ₄			—	—	—	—	—	—	—	—
VT- ¹ / ₄ -3- ¹ / ₄	LK- ¹ / ₄	G ¹ / ₄	39	10	21	77.5	8	—	—	—	54
	TK- ¹ / ₄			—	—	—	—	—	—	—	—
VT- ³ / ₈ -2- ³ / ₈	LK- ³ / ₈	G ³ / ₈	43	12.4	24	70	10.5	14.1	40.3	—	22
	TK- ³ / ₈			—	—	—	—	—	—	—	—
VT- ³ / ₈ -3- ³ / ₈	LK- ³ / ₈	G ³ / ₈	43	12.5	24	96	11	—	—	—	66.5
	TK- ³ / ₈			—	—	—	—	—	—	—	—

Connection of outlets	Hollow bolt						Optional ring pieces			
	Supply line	No. of ring pieces	Order code		Material	Weight kg	Order code		Material	Weight
			Part No.	Type			Part No.	Type		
G ¹ / ₈	G ¹ / ₈	2	206 146	VT- ¹ / ₈ -2	Galvanized steel	0,021	9181	LK- ¹ / ₈	Aluminium with 2 sealing rings	0.006
		3	004 596	VT- ¹ / ₈ -3		0.027	9182	TK- ¹ / ₈		0.008
G ¹ / ₄	G ¹ / ₄	2	009 177	VT- ¹ / ₄ -2- ¹ / ₄	Galvanized steel	0.036	9173	LK- ¹ / ₄	Aluminium with 2 sealing rings	0.015
		3	009 178	VT- ¹ / ₄ -3- ¹ / ₄		0.044	9174	TK- ¹ / ₄		0.020
G ³ / ₈	G ³ / ₈	2	009 179	VT- ³ / ₈ -2- ³ / ₈	Galvanized steel	0.046	9175	LK- ³ / ₈	Aluminium with 2 sealing rings	0.020
		3	009 180	VT- ³ / ₈ -3- ³ / ₈		0.056	9176	TK- ³ / ₈		0.025