

Hose Type P-...



Pressure range*		0 to 10 bar				
Temperature range		- 10 to + 80 °C				
Order code		Inside dia. mm	Outside dia. mm	Min. bend- ing radius	Material	Weight kg/m
Part No.	Type					
2231	P-6	6	13	40	Perbunan	0.145
2232	P-9	9	16	50		0.185
2234	P-13	13	24	100	Buna N	0.400
2235	P-19	19	30	200		0.719


Hose Type PC-...



Pressure range*		0 to 10 bar			
Temperature range		– 10 to +35 °C			
Order code		Inside dia. mm	Outside dia. mm	Material	Weight kg/m
Part No.	Type				
5030	PC-6	6	12	PVC with fabric	0.144
5031	PC-9	9	15		0.139

* The maximum pressure is permissible at the maximum temperature

Barbed fitting (male) Type N-... with sealing ring

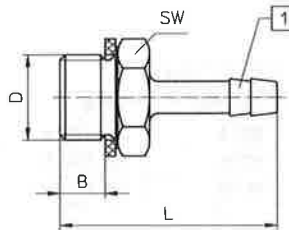

Brass equipment Type N-...-MS

1 Connection nipple for synthetic tube

Order code		For hose inside dia.	Connection D	Nominal size mm	Material	Weight kg	Dimensions		
Part No.	Type						B	L	SW
3605	N-1/8-P-6	6	G 1/8	4.5	Blue anodized aluminium	0.014	7	36	13
3606	N-1/4-P-6	6	G 1/4	4.5		0.021	9	38	17
3608	N-3/8-P-6	6	G 3/8	4.5		0.034	11	41	19
3607	N-1/4-P-9	9	G 1/4	6.5		0.024	9	38	17
3609	N-3/8-P-9	9	G 3/8	8		0.031	11	41	19
36160	N-3/8-P-13	13	G 3/8	11		0.035	8.5	46.9	19
3610	N-1/2-P-9	9	G 1/2	8		0.061	11.5	43.9	24
3611	N-1/2-P-13	13	G 1/2	11		0.063	11.5	49.9	24
3612	N-3/4-P-13	13	G 3/4	11		0.113	12	52.4	32
3613	N-3/4-P-19	19	G 3/4	16		0.117	12	58.4	32

Order code		For hose inside dia.	Connection D	Nominal size mm	Material	Weight kg	Dimensions		
Part No.	Type						B	L	SW
15630	N-1/8-P-6-MS	6	G 1/8	4.5	Brass	0.010	7	36	13
15631	N-1/4-P-6-MS	6	G 1/4	4.5		0.015	6.5	38	17
15632	N-1/4-P-6-MS	9	G 1/4	6.5		0.020	6.5	38	17
15633	N-3/8-P-6-MS	6	G 3/8	4.5		0.030	8.5	41	19
15634	N-3/8-P-9-MS	9	G 3/8	7.6		0.035	8.5	41	19
36161	N-3/8-P-13-MS	13	G 3/8	11		0.040	8.5	46.9	19
15635	N-1/2-P-9-MS	9	G 1/2	8		0.050	11.5	43.9	24
15636	N-1/2-P-13-MS	13	G 1/2	11		0.055	11.5	49.9	24
15637	N-3/4-P-13-MS	19	G 3/4	16.5		0.105	12	58.4	32
15638	N-3/4-P-19-MS	19	G 3/4	16.5		0.105	12	58.4	32