


Micro stem actuated valve SO-3-PK-3-B

Part number: 10403

FESTO

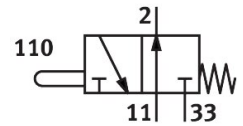

[PDF](#) General operating condition

Data sheet

Feature	Value
Valve function	3/2 open, monostable
Type of actuation	Mechanical
Standard nominal flow rate (standardised to DIN 1343)	60 l/min
pneumatic working port	PK-3
Operating pressure	-0.95 bar ... 8 bar
Type of reset	Mechanical spring
Nominal size	1.8 mm
Type of piloting	Direct
Symbol	00991109
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-10 °C ... 60 °C
Actuating force	6 N
Product weight	7 g
Type of mounting	With through-hole
Pneumatic connection, port 1	PK-3
Pneumatic connection, port 2	PK-3
Material housing	POM