 




Pneumatic valve J-3-PK-3

Part number: 10772

FESTO

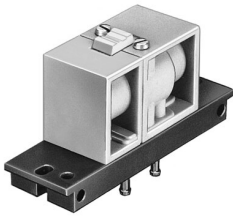

 General operating condition

Data sheet

| Feature | Value |
|---|--|
| Valve function | 3/2 bistable |
| Standard nominal flow rate (standardised to DIN 1343) | 100 l/min |
| pneumatic working port | PK-3 |
| Operating pressure | -0.9 bar ... 8 bar |
| Design | Piston gate valve |
| Nominal size | 2.5 mm |
| Symbol | 00991377 |
| Switching time reversal | 7 ms |
| Explosion protection | The information in the certificate must be observed! Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX) |
| Operating medium | Compressed air to ISO 8573-1:2010 [7:-:-] |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Ambient temperature | -10 °C ... 60 °C |
| Product weight | 75 g |
| Type of mounting | On sub-base On mounting frame With through-hole |
| Auxiliary pilot air port 12 | PK-3 |
| Auxiliary pilot air port 14 | PK-3 |
| Pneumatic connection, port 1 | PK-3 |
| Pneumatic connection, port 4 | PK-3 |
| Pneumatic connection, port 5 | PK-3 |
| Material sub-base | Brass PPS reinforced |
| Material seals | NBR |
| Material housing | Die-cast zinc |