


Silencer AMTE-M-LH-U10

Part number: 1206994

FESTO

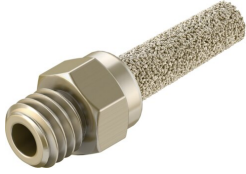

[PDF](#) [General operating condition](#)

Data sheet

| Feature | Value |
|------------------------------------|---|
| Mounting position | optional |
| Size of pack | 20 |
| Symbol | 00991473 |
| Operating pressure | 0 MPa ... 1 MPa |
| Operating pressure | 0 bar ... 10 bar |
| Flow rate to atmosphere | 260 l/min |
| Operating medium | Compressed air to ISO 8573-1:2010 [7::-:] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Sound pressure level | 71 dB(A) |
| Ambient temperature | -40 °C ... 80 °C |
| Product weight | 1.7 g |
| Pneumatic connection | 10-32 UNF-2A |
| Material shock absorber insert | Bronze |
| Material screwed plug | Brass |
| Note on materials | RoHS-compliant |