


End plate kit NEV-3DA/DB-NPT

Part number: 13997

FESTO

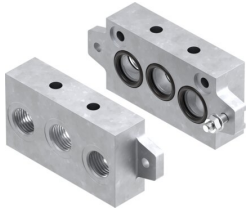

 [General operating condition](#)

Data sheet

Feature	Value
Width	190 mm
Operating pressure	0 bar ... 16 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Mounting method for sub-base	With through-hole
Mounting method for valve	Screw-in
Pneumatic connection, port 1	NPT1-11 1/2
Pneumatic connection, port 3	NPT1-11 1/2
Pneumatic connection, port 5	NPT1-11 1/2