


Axial kit EAMM-A-R38-60H

Part number: 1456630

FESTO

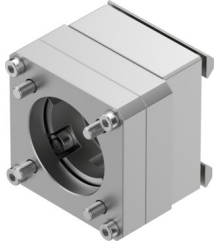

 [General operating condition](#)

Data sheet

Feature	Value
Nominal length	46 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C ... 60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C ... 60 °C
Mass moment of inertia	3.5 kgmm ²
Transmittable torque	4.4 Nm
Product weight	390 g
Interface code, actuator	R38
Interface code, motor in	60H
Note on materials	RoHS-compliant