



Clamping module EV-20-4

Part number: 150683

FESTO

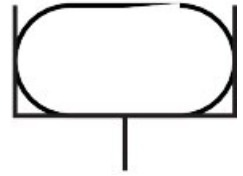

Data sheet

 General operating condition

Feature	Value
Stroke	4 mm
Clamping surface	Ø 20
Mounting position	optional
Mode of operation	Single-acting
Symbol	00991208
Operating pressure	≤0.6 MPa
Operating pressure	≤6 bar
Operating pressure	≤87 psi
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C ... 40 °C
Product weight	19 g
Type of mounting	With through-hole
Pneumatic connection	M3
Material housing	Die-cast aluminium
Material membrane	TPE-U(PU)