


Profile mounting EAHF-V2-80/100-P

Part number: 1547780

FESTO

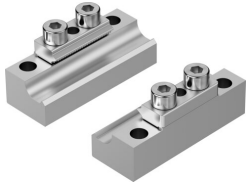

 [General operating condition](#)

Data sheet

| Feature | Value |
|---|--|
| Corrosion resistance class CRC | 3 - high corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Suitability for the production of Li-ion batteries | Suitable for battery production with reduced Cu/Zn/Ni values (F1a) |
| Cleanroom suitability, measured according to ISO 14644-14 | Element installed statically, no meaningful evaluation possible according to ISO 14644-1 |
| Max. load capacity | 1.6 kN |
| Product weight | 570 g |
| Note on materials | RoHS-compliant |