


# Profile mounting EAHF-V2-50/63-P

Part number: 1547781

FESTO

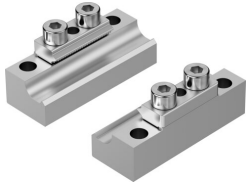

 [General operating condition](#)

## Data sheet

Feature	Value
Corrosion resistance class CRC	3 - high corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper, zinc or nickel are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils.
Cleanroom suitability, measured according to ISO 14644-14	Element installed statically, no meaningful evaluation possible according to ISO 14644-1
Max. load capacity	3.6 kN
Product weight	340 g
Note on materials	RoHS-compliant