


Branching module PMBL-186-HP3-H

Part number: 1609073

FESTO

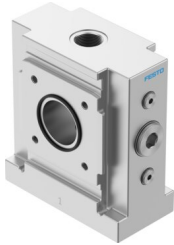

 General operating condition

Data sheet

Feature	Value
Nominal size DN	54
Series	L
Mounting position	optional
Design	Branching module
Symbol	00991510
Operating pressure	0 MPa ... 5 MPa
Operating pressure	0 bar ... 50 bar
CE mark (see declaration of conformity)	In accordance with EU Pressure Equipment Directive
UKCA marking (see declaration of conformity)	to UK Pressure Equipment Regulations
Operating medium	Compressed air to ISO 8573-1:2010 [-:-:-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-10 °C ... 60 °C
Suitable for use with food	See supplementary material information
Media temperature	5 °C ... 60 °C
Ambient temperature	5 °C ... 60 °C
Pneumatic connection, port 3	G1
Pneumatic connection, port 4	G1
Note on materials	RoHS-compliant
Material seals	NBR
Material housing	Wrought aluminium alloy