


# Module connector PAML-MK-186-HP3

Part number: 1629377

FESTO

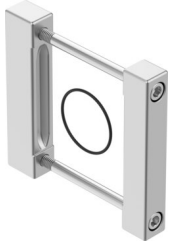

 [General operating condition](#)

## Data sheet

| Feature                        | Value                                    |
|--------------------------------|--|
| Size                           | 186                                      |
| Nominal size DN                | 54                                       |
| Series                         | L  |
| Operating pressure             | 0 MPa ... 5 MPa                          |
| Operating pressure             | 0 bar ... 50 bar                         |
| Operating medium               | Compressed air to ISO 8573-1:2010 [-::-] |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress            |
| LABS (PWIS) conformity         | VDMA24364-B2-L                           |
| Storage temperature            | -10 °C ... 60 °C                         |
| Suitable for use with food     | See supplementary material information   |
| Media temperature              | 5 °C ... 60 °C                           |
| Ambient temperature            | 5 °C ... 60 °C                           |
| Product weight                 | 1300 g                                   |
| Note on materials              | RoHS-compliant                           |
| Material seals                 | NBR                                      |
| Material module connector      | Wrought aluminium alloy                  |
| Material screws                | Stainless steel                          |