


# Filter LF-3/4-D-MIDI-NPT

Part number: 173696

FESTO

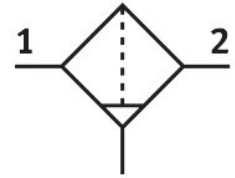

General operating condition

## Data sheet

Feature	Value
Size	Midi
Series	D
Mounting position	Vertical
Grade of filtration	40 µm
Condensate drain	Manual, non-detenting
Bowl guard	Metal bowl guard
Symbol	00991519
Operating pressure	0 bar ... 16 bar
Standard nominal flow rate (standardised to DIN 1343)	3000 l/min
Operating medium	Inert gas
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-10 °C ... 60 °C
Air purity class at output	Compressed air to ISO 8573-1:2010 [7:8:4] Inert gases
Media temperature	-10 °C ... 60 °C
Ambient temperature	-10 °C ... 60 °C
Type of mounting	Via mounting bracket
Pneumatic connection, port 1	3/4 NPT
Pneumatic connection, port 2	3/4 NPT
Note on materials	RoHS-compliant
Material filter	PE
Material housing	Die-cast zinc
Material bowl	PC