


Swivel flange SNC-32

Part number: 174383

FESTO

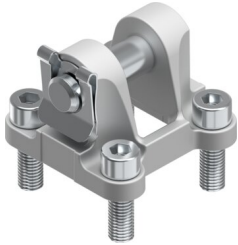

 [General operating condition](#)

Data sheet

| Feature | Value |
|--------------------------------|---|
| Size | 32 |
| Based on standard | ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290) |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364-B2-L |
| Ambient temperature | -40 °C ... 150 °C |
| Max. load capacity | 0.9 kN |
| Product weight | 93 g |
| Note on materials | RoHS-compliant |
| Material mounting | Die-cast aluminium |
| Material bolt | Steel Galvanised |
| Material screws | Steel Galvanised |
| Material lock | Spring steel Galvanised |