


# Swivel flange SNCS-63

Part number: 174400

FESTO

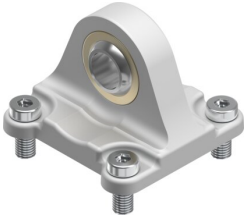

 [General operating condition](#)

## Data sheet

Feature	Value
Size	63
Based on standard	ISO 15552 (previously also VDMA 24562, ISO 6431, NF E49 003.1, UNI 10290)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-40 °C ... 150 °C
Max. load capacity	4 kN
Product weight	281 g
Note on materials	RoHS-compliant
Material mounting	Die-cast aluminium
Material rod end bearing	Steel PTFE
Material screws	Steel Galvanised