


Distributor CQD-12/15/18/22

Part number: 177717

FESTO

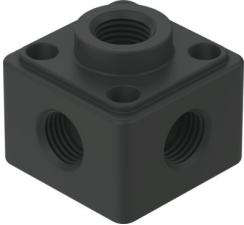

 [General operating condition](#)

Data sheet

Feature	Value
Nominal size	18.6 mm
Mounting position	optional
Size of pack	1
Operating pressure complete temperature range	-0.95 bar ... 7 bar
Temperature-dependent operating pressure	-0.95 bar ... 15 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Media temperature	-25 °C ... 75 °C
Ambient temperature	-25 °C ... 70 °C
Nominal torque	2.5 Nm
Tolerance for nominal tightening torque	± 10%
Number of outputs	4
Number of supply lines	1
Pneumatic connection, port 1	Female thread G1/2
Pneumatic connection, port 2	Female thread G1/2
Note on materials	RoHS-compliant
Material housing	POM